

AC AND MC CABLE GAYLORDS

Continuous Length of MC or AC Cable up to 6,000 ft



Our newest packaging solution is geared towards electrical contractors and OEMs that are focused on prefabrication and agile construction. The gaylord put-up will provide one continuous length of MC and AC cable targeted at 6K ft.


Benefits

- Reduce material handling and scrap
- Significant savings and operational efficiencies
- Provides flexibility - automation



For more info visit atkore.com/afc



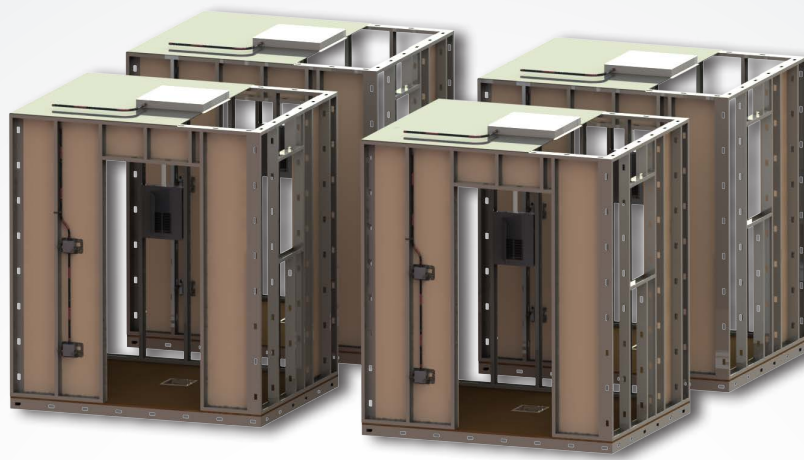

Product Code	Trade Size	Grounding Conductor AWG	Length (ft)	Approx. Weight/ 1000 Feet (lb)	Armor Nominal O.D. (in)
MC LITE® PLAIN					
2104-76-00	12-2 Solid (Black, White)	12 (Solid Green)	6000	110	0.495
2104-76-01	12-2 Solid (Brown, Gray)	12 (Solid Green)	6000	110	0.495
2158-76-00	12-2 Stranded (Black, White)	12 (Stranded Green)	6000	110	0.495
MC TUFF LUMINARY® BLUE ARMOR					
18BEB76T500*	16-2 (1TPJ) (Purple, Gray) 12-2 Solid (Black, White)	12 (Solid Green)	6000	237	0.626
18BEB76T501*	16-2 (1TPJ) (Purple, Gray) 12-2 Solid (Brown, Gray)	12 (Solid Green)	6000	237	0.626
MC LITE LUMINARY®					
18BF-76-500*	16-2 (1TPJ) (Purple, Gray) 12-2 Solid (Black, White)	12 (Solid Green)	6000	156	0.626
18BF-76-501*	16-2 (1TPJ) (Purple, Gray) 12-2 Solid (Brown, Gray)	12 (Solid Green)	6000	156	0.626
MC TUFF® BLUE ARMOR					
1704B76T00*	12-2 Solid (Black, White)	12 (Solid Green)	6000	147	0.495
1704B76T01*	12-2 Solid (Brown, Gray)	12 (Solid Green)	6000	147	0.495
MC-QUIK® LITE PLAIN					
3104Z76-00	12-2 Solid (Black, White)	10 Aluminum Bond/Ground	6000	90	0.463
3104Z76-01	12-2 Solid (Brown, Gray)	10 Aluminum Bond/Ground	6000	90	0.463

NOTE: Additional cables available upon request, made to order, subject to lead times

* Subject to minimums and lead times

